

Motorfeedback-System **CNS50-AZA0-S13** Order number 1 033 992

compatible to:




CDD 50 C5
6D0 100 200 006

	CNS50-AZA0-S13 Order number 1 033 992	CDD 50 C5* 6D0 100 200 006
Housing colour	-----	-----
Cable colour	-----	-----
Lable	-----	-----
Marking	Serialnumber	Serialnumber
		*No longer available!

CNS50-AZA0-S13

Type according to productinfo 8010625 but with following changes:

- CT stator coupling
- flex strip pcb with 17pin connector insert (15pins only assembled)
- flex strip pcb with partial strengthening at the 17pin connector insert
- flex strip pcb fixed on housing with adhesive tape
- shield wire connected to pin3 (17pin connector insert)

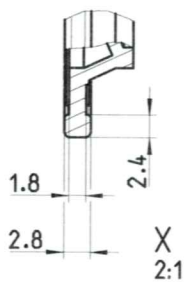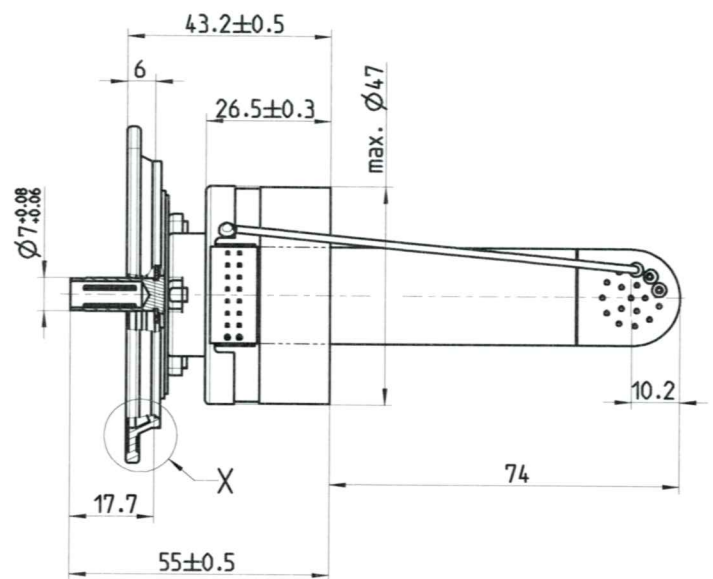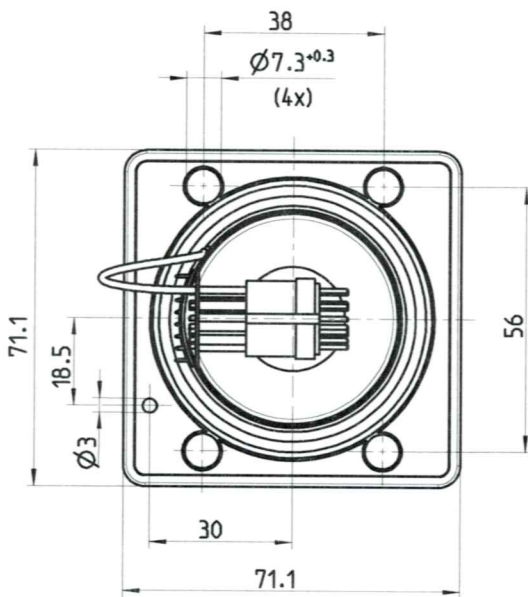

Number of pulses per revolution
4096

Commutation
2 = 4pole

Scope of delivery:

Pin allocation 916 000 100 481

CNS50-AZA0-S13

Pin allocation

for CNS50-AZA0-S01, CNS50-AZA0-S13, CNS50-AZA0-S14

Pin Connector (16p) Berg	Pin Connector (17p) Interconnectron	Signal Stegmann	Signal C.T.D
1	17	GND	GND
2	4	R	S1
3	7	S	$\overline{S2}$
4	8	T	S3
5	11	K0	INDEX
6	14	K2	CH B
7	10	K1	CH A
8	-	N. C.	-
9	16	Us	+5 V DC
10	5	\overline{R}	$\overline{S1}$
11	6	\overline{S}	S2
12	9	\overline{T}	$\overline{S3}$
13	12	$\overline{K0}$	\overline{INDEX}
14	15	$\overline{K2}$	\overline{CHB}
15	13	$\overline{K1}$	\overline{CHA}
16	-	N. C.	-
Encoder housing	3	Shield	Shield

CNS50-AZA0-S13

Contact:

Australia	Phone	+61 3 94 97 41 00 1800 33 48 02 – toll free
	E-Mail	sales@sick.com.au
Belgique/ Luxembourg	Phone	+32 (0)2 466 55 66
	E-Mail	info@sick.be
Brasil	Phone	+55 11 50 91 49 00
	E-Mail	sac@sick.com.br
Ceska` Republika	Phone	+42 02 57 91 18 50
	E-Mail	sick@sick.cz
China	Phone	+8 52 27 63 69 66
	E-Mail	ghk@sick.com.hk
Danmark	Phone	+45 45 82 64 00
	E-Mail	sick@sick.dk
Deutschland	Phone	+49 (0)2 11 53 01 250
	E-Mail	vzdinfo@sick.de
España	Phone	+34 93 480 31 00
	E-Mail	info@sick.es
France	Phone	+33 1 64 62 35 00
	E-Mail	info@sick.fr
Great Britain	Phone	+44 (0)17 27 83 11 21
	E-Mail	info@sick.co.uk
Italia	Phone	+39 011 79 79 65
	E-Mail	stegmann@stegmann.it
Japan	Phone	+81 (0)3 33 58 13 41
	E-Mail	info@sick.jp
Korea	Phone	+82 27 86 63 21/4
	E-Mail	kang@sickkorea.net
Nederland	Phone	+31 (0)30 229 25 44
	E-Mail	info@sick.nl
Norge	Phone	+47 67 81 50 00
	E-Mail	austefjord@sick.no
Österreich	Phone	+43 (0)22 36 62 28 8-0
	E-Mail	office@sick.at
Polska	Phone	+48 22 837 40 50
	E-Mail	info@sick.pl
Schweiz	Phone	+41 41 619 29 39
	E-Mail	contact@sick.ch
Singapore	Phone	+65 67 44 37 32
	E-Mail	admin@sicksgp.com.sg
Suomi	Tel.	+35 89 25 15 800
	E-Mail	sick@sick.fi
Sverige	Phone	+46 8 680 64 50
	E-Mail	info@sick.se
Taiwan	Phone	+88 62 23 65 62 92
	E-Mail	sickgrc@ms6.hinet.net
USA	Phone	+19 37 454 19 56
	E-Mail	sales@stegmann.com

More representatives and agencies

In all major industrial nations at www.sick.com

Sick AG • Industrial Sensors • Waldkirch • Germany • www.sick.com
SICK STEGMANN GmbH • Donaueschingen • Germany • www.sick-stegmann.de

Subject to change without prior notice • The specified product features and technical data do not represent any guarantee