

Motorfeedback-System **SRM50-HZV0-S01**

Order number 1 034 152

compatible to:


SRM 50 C9
6CR 100 200 018

	SRM50-HZV0-S01 Order number 1 034 152	SRM 50 C9* 6CR 100 200 018
Housing colour	-----	-----
Cable colour	-----	-----
Lable	-----	-----
Marking	Serialnumber	Serialnumber *No longer available!

SRM50-HZV0-S01

Equivalent to SRM50-HAA0-K01 according to productinfo no. 8010613, but with following changes:

- CT stator coupling with index hole
- with earth-strips
- cable output, length 200 mm
- screen wire soldered on housing
- dimensions and construction see drawing below

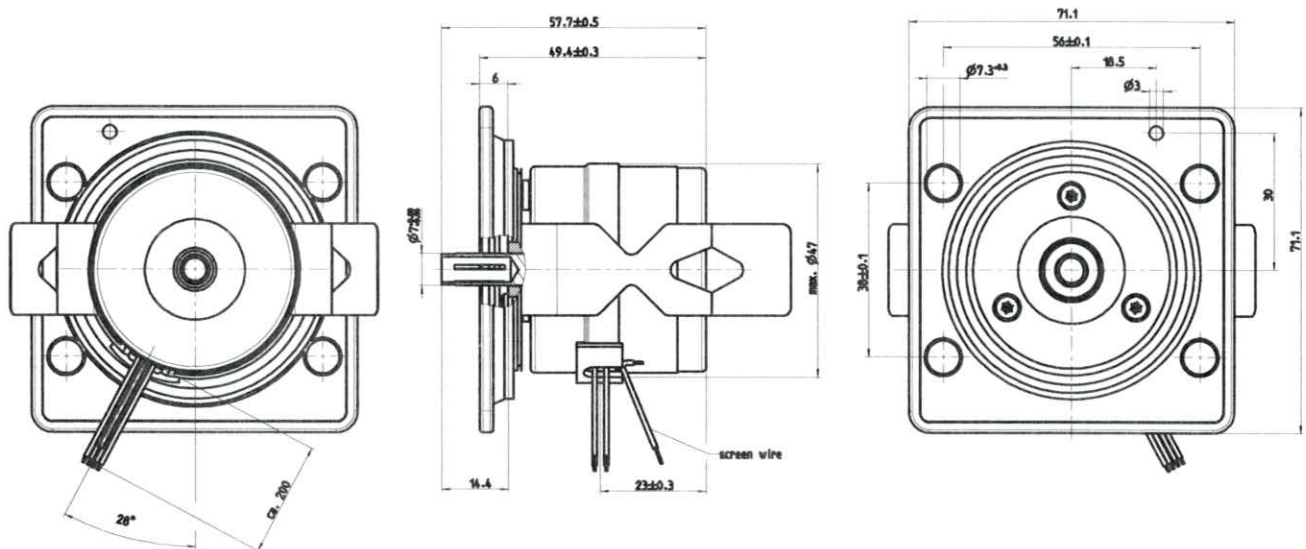

Contact:

Australia	Phone	+61 3 94 97 41 00 1800 33 48 02 – toll free
	E-Mail	sales@sick.com.au
Belgique/ Luxembourg	Phone	+32 (0)2 466 55 66
	E-Mail	info@sick.be
Brasil	Phone	+55 11 50 91 49 00
	E-Mail	sac@sick.com.br
Ceska` Republika	Phone	+42 02 57 91 18 50
	E-Mail	sick@sick.cz
China	Phone	+8 52 27 63 69 66
	E-Mail	ghk@sick.com.hk
Danmark	Phone	+45 45 82 64 00
	E-Mail	sick@sick.dk
Deutschland	Phone	+49 (0)2 11 53 01 250
	E-Mail	vzdinfo@sick.de
España	Phone	+34 93 480 31 00
	E-Mail	info@sick.es
France	Phone	+33 1 64 62 35 00
	E-Mail	info@sick.fr
Great Britain	Phone	+44 (0)17 27 83 11 21
	E-Mail	info@sick.co.uk
Italia	Phone	+39 011 79 79 65
	E-Mail	stegmann@stegmann.it
Japan	Phone	+81 (0)3 33 58 13 41
	E-Mail	info@sick.jp
Korea	Phone	+82 27 86 63 21/4
	E-Mail	kang@sickkorea.net
Nederland	Phone	+31 (0)30 229 25 44
	E-Mail	info@sick.nl
Norge	Phone	+47 67 81 50 00
	E-Mail	austefjord@sick.no
Österreich	Phone	+43 (0)22 36 62 28 8-0
	E-Mail	office@sick.at
Polska	Phone	+48 22 837 40 50
	E-Mail	info@sick.pl
Schweiz	Phone	+41 41 619 29 39
	E-Mail	contact@sick.ch
Singapore	Phone	+65 67 44 37 32
	E-Mail	admin@sicksgp.com.sg
Suomi	Tel.	+35 89 25 15 800
	E-Mail	sick@sick.fi
Sverige	Phone	+46 8 680 64 50
	E-Mail	info@sick.se
Taiwan	Phone	+88 62 23 65 62 92
	E-Mail	sickgrc@ms6.hinet.net
USA	Phone	+19 37 454 19 56
	E-Mail	sales@stegmann.com

More representatives and agencies
In all major industrial nations at www.sick.com